

Vibratory hopper

NVD3/5 - NVD4/40





- Complete empty run up to the last part
- Filling quantities from 5 l up to 40 l
- Filling weight of up to 20 kg

Dimensions and dimension drawings

NVD

Type	NVD3/5	NVD4/10	NVD4/15	NVD4/20	NVD4/40
A	300 mm	426 mm	426 mm	426 mm	426 mm
B	260 mm	360 mm	360 mm	360 mm	360 mm
C	98 mm	163 mm	163 mm	163 mm	163 mm
D	72 mm	115 mm	115 mm	115 mm	115 mm
E	11 mm	16 mm	16 mm	16 mm	16 mm
F	164 mm	214 mm	214 mm	214 mm	214 mm
G	546 mm	695 mm	740 mm	796 mm	999.5 mm
H	121 mm	141 mm	197 mm	216 mm	310 mm
I	94 mm	124 mm	125 mm	194 mm	194 mm
K	163 mm	229 mm	251 mm	316 mm	369.3 mm
L	295 mm	384 mm	424 mm	444 mm	524 mm
M	180 mm	182.5 mm	207 mm	252 mm	396.5 mm

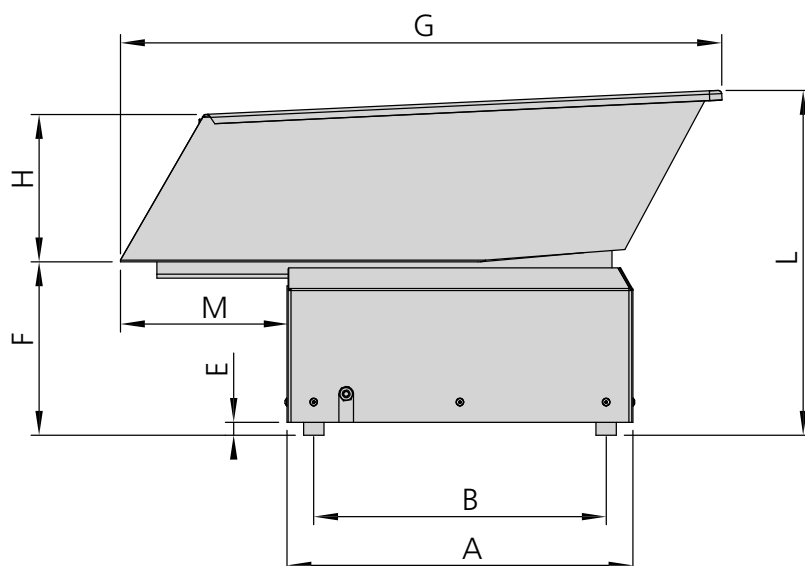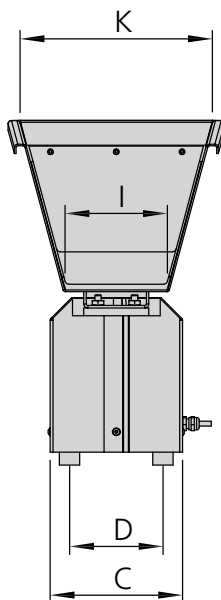



NVD	
Operating temperature	10 - 45 °C

Type	NVD3/5	NVD3/5	NVD4/10	NVD4/10	NVD4/15	NVD4/15
Order number	50439542	50439547	50439543	50439548	50439544	50439549
Mains connection (mains voltage/mains frequency)	230 V/50 Hz	115 V/60 Hz	230 V/50 Hz	115 V/60 Hz	230 V/50 Hz	115 V/60 Hz
Max. power consumption	46 VA	23 VA	184 VA	92 VA	184 VA	92 VA
Net weight	15.4 kg	15.4 kg	41 kg	41 kg	42.4 kg	42.4 kg
Load volume	5 l	5 l	10 l	10 l	15 l	15 l
Maximum filling weight	9 kg	9 kg	20 kg	20 kg	20 kg	20 kg
Arithmetical mean roughness value Ra	< 0.8 µm	< 0.8 µm	< 0.8 µm	< 0.8 µm	< 0.8 µm	< 0.8 µm
Mean roughness depth Rz	4.5 µm	4.5 µm	4.5 µm	4.5 µm	4.5 µm	4.5 µm
Protection type	IP54	IP54	IP54	IP54	IP54	IP54

Type	NVD4/20	NVD4/20	NVD4/40	NVD4/40
Order number	50439545	50439550	50439546	50439552
Mains connection (mains voltage/mains frequency)	230 V/50 Hz	115 V/60 Hz	230 V/50 Hz	115 V/60 Hz
Max. power consumption	184 VA	92 VA	184 VA	92 VA
Net weight	44.2 kg	44.2 kg	49.4 kg	49.4 kg
Load volume	20 l	20 l	40 l	40 l
Maximum filling weight	20 kg	20 kg	20 kg	20 kg
Arithmetical mean roughness value Ra	< 0.8 µm	< 0.8 µm	< 0.8 µm	< 0.8 µm
Mean roughness depth Rz	4.5 µm	4.5 µm	4.5 µm	4.5 µm
Protection type	IP54	IP54	IP54	IP54

Note: --- = nonexistent