

Control device

SIGA




- Integrated, adjustable soft start guarantees jerk-free starting of the vibration feeder
- Electronic frequency control unit for continuously variable control of inductive loads
- Frequency setting in 0.1 Hz steps

Dimensions and dimension drawings

SIGA

Type	SIGA
A	200 mm
B	100 mm
C	80 mm
D	4 mm
E	20 mm

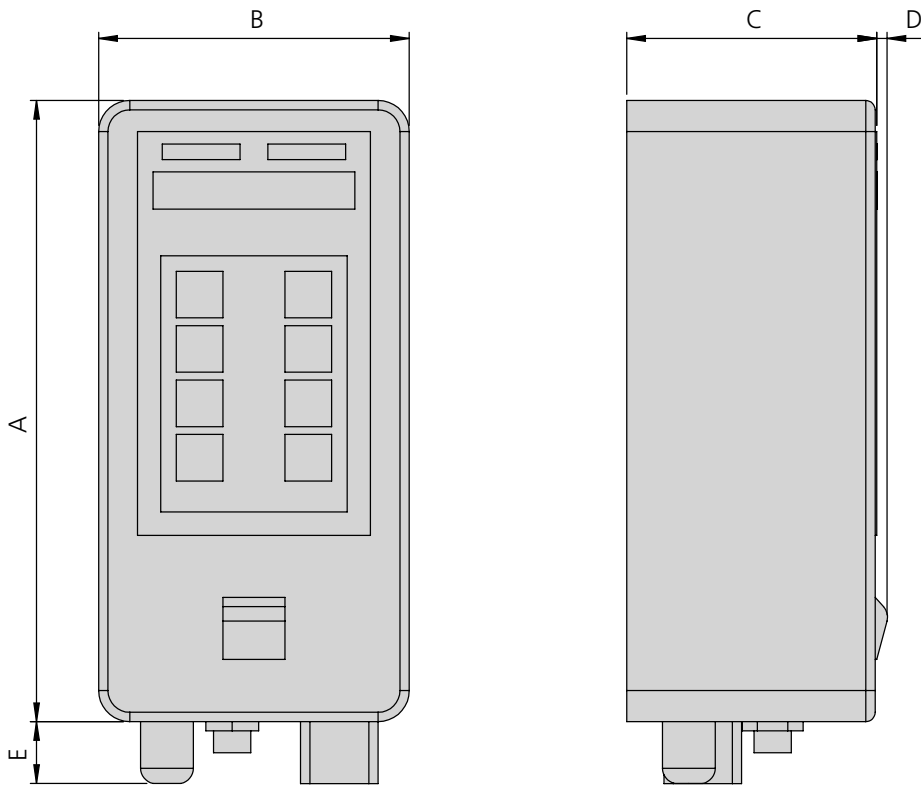



SIGA	
Operating temperature	0 - 50 °C
Type	SIGA
Order number	50195031
Nominal output current	0.025 - 5 A
Output frequency	5 - 200 Hz
Frequency	50 Hz
Input voltage	230 VAC
Output voltage	50 - 200 VAC
Net weight	1.7 kg
Fuses	2x6.3 A (F)
Protection type	IP54