

MODEL NO.

**TVH-M20GNPM**

PRODUCT LINE

**Valvetop Discrete Valve Controller**

SPECIFICATIONS

**Model** Valvetop Model TVH, 316 Stainless Steel base and lid

**Bus Sensor** (2) Mech SPDT (10A@250VAC)


**Area Classification** Class 1, Div. 1, Groups A,B,C&D; IP67,4,4X  
Class 2, Div. 1, Groups E,F&G  
Ex ia IIC T4, Ex tb IIIC T135° Db, IP64

**Visual Display Shaft** 90° Green Open / Red Closed  
NAMUR, 304 Stainless Steel

**Conduit Entries** (2) 1/2" NPT

**O-Rings** Silicone

**Temperature Rating**-50 °C to 60 °C

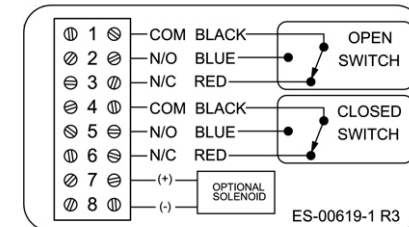

Current as of Jul 31, 2013 - subject to change without notice.

**TOPWORX**

TopWorx, Inc. (502) 969-8000 ph.  
3300 Fern Valley Rd. (502) 969-5911 fax  
Louisville, KY 40213 www.topworx.com